


# SEOOW-18-4BK-1 Cut Sheet

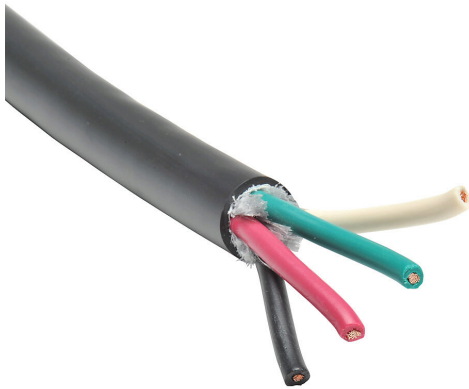

Southwire portable cord, unshielded, SEOOW, 600V, 4 conductors (includes ground), 18 AWG, TPE conductor insulation material, black, white, red and green, TPE jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SEOOW-18-4BK-1>

## Technical Specifications

<b>Brand</b>	Southwire
<b>Item</b>	Cord
<b>Wire/Cable Type</b>	Portable
<b>UL Wire/Cable Type</b>	SEOOW
<b>Applicable Standards</b>	UL 62
<b>Application</b>	General purpose
<b>Flexibility</b>	Flexible
<b>Voltage Rating</b>	600V
<b>Conductors</b>	4 conductors (includes ground)
<b>Conductor Size</b>	18 AWG
<b>Conductor Stranding</b>	16-stranded
<b>Conductor Material</b>	Bare copper
<b>Conductor Insulation Material</b>	TPE
<b>Conductor Insulation Color</b>	Black, white, red and green

<b>Shielding</b>	Unshielded
<b>Jacket Material</b>	TPE
<b>Jacket Color</b>	Black
<b>Nominal Overall Cable Diameter</b>	0.395in
<b>Bulk Length</b>	Cut to length
<b>Package Type</b>	<ul style="list-style-type: none"><li>• 20 to 50ft = Coil</li><li>• 51 to 250ft = 14 x 7in Reel</li><li>• 251 to 355ft = 14 x 10in Reel</li><li>• 356 to 545ft = 16 x 10in Reel</li><li>• 546 to 765ft = 18 x 10in Reel</li><li>• 766 to 995ft = 18 x 13in Reel</li><li>• 996 to 2225ft = 24 x 17in Wooden Reel</li><li>• 2226 to 3560ft = 30 x 17in Wooden Reel</li><li>• 3561 to 5000ft = Large Wooden Reel</li></ul>

## Agency Approvals

<b>UL Listed File #</b>	E46194
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	90458
<b>RoHS Status</b>	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>
<b>Other</b>	<a href="#">RoHS Statement</a>