


SEOOW-18-4BK-1 Cut Sheet

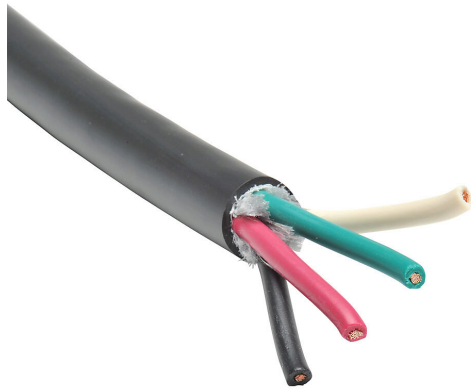

Southwire portable cord, unshielded, SEOOW, 600V, 4 conductors (includes ground), 18 AWG, TPE conductor insulation material, black, white, red and green, TPE jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SEOOW-18-4BK-1>

Technical Specifications

| | |
|--------------------------------------|--------------------------------|
| Brand | Southwire |
| Item | Cord |
| Wire/Cable Type | Portable |
| UL Wire/Cable Type | SEOOW |
| Applicable Standards | UL 62 |
| Application | General purpose |
| Flexibility | Flexible |
| Voltage Rating | 600V |
| Conductors | 4 conductors (includes ground) |
| Conductor Size | 18 AWG |
| Conductor Stranding | 16-stranded |
| Conductor Material | Bare copper |
| Conductor Insulation Material | TPE |
| Conductor Insulation Color | Black, white, red and green |

| | |
|---------------------------------------|---|
| Shielding | Unshielded |
| Jacket Material | TPE |
| Jacket Color | Black |
| Nominal Overall Cable Diameter | 0.395in |
| Bulk Length | Cut to length |
| Package Type | 1 to 50ft = Coil, 51 to 250ft = 14 x 7in Reel, 251 to 350ft = 14 x 10in Reel, 351 to 550ft = 16 x 10in Reel, 551 to 780ft = 18 x 10in Reel, 781 to 1010ft = 18 x 13in Reel, 1011 to 2180ft = 24 x 17in Wooden Reel, 2181 to 3590ft = 30 x 17in Wooden Reel, 3591 to MAX = Large Wooden Reel |

Agency Approvals

| | |
|-----------------------------|---|
| UL Listed File # | E46194 |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | None |
| CSA File # | 90458 |
| RoHS Status | Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below) |
| EU REACH | View EU REACH document |
| Other | RoHS Statement |