


SJC-55C-22.225 Cut Sheet

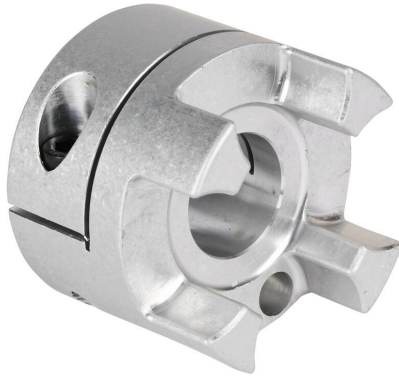

Sung-II Machinery drive coupling hub, jaw type, aluminum alloy, clamp, size 55, 7/8in bore. Requires SJC-55 series spiders.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SJC-55C-22.225>

Technical Specifications

Brand	Sung-II Machinery
Item	Drive coupling hub
Coupling Type	Jaw type
Material	Aluminum alloy
Maximum Angular Misalignment	1.0 degrees
Maximum RPM	6500
Attachment Style	Clamp

Coupling Size	55
Bore Diameter	7/8in
Outside Diameter	55mm
Clamp Screw Fastening Torque	13N-m
Clamp Screw Size	M6
Requires	SJC-55 series spiders

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/SJC-55C-22.225.pdf>
See store item page for other formats.