


# SJEOOW-12-4BK-1 Cut Sheet

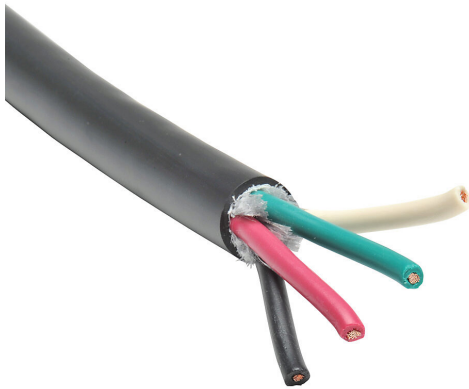

Southwire portable cord, unshielded, SJEOOW, 300V, 4 conductors (includes ground), 12 AWG, TPE conductor insulation material, black, white, red and green, TPE jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SJEOOW-12-4BK-1>

## Technical Specifications

<b>Brand</b>	Southwire
<b>Item</b>	Cord
<b>Wire/Cable Type</b>	Portable
<b>UL Wire/Cable Type</b>	SJEOOW
<b>Applicable Standards</b>	UL 62
<b>Application</b>	General purpose
<b>Flexibility</b>	Flexible
<b>Voltage Rating</b>	300V
<b>Conductors</b>	4 conductors (includes ground)
<b>Conductor Size</b>	12 AWG
<b>Conductor Stranding</b>	65-stranded
<b>Conductor Material</b>	Bare copper
<b>Conductor Insulation Material</b>	TPE
<b>Conductor Insulation Color</b>	Black, white, red and green

<b>Shielding</b>	Unshielded
<b>Jacket Material</b>	TPE
<b>Jacket Color</b>	Black
<b>Nominal Overall Cable Diameter</b>	0.48in
<b>Bulk Length</b>	Cut to length
<b>Package Type</b>	<ul style="list-style-type: none"><li>• 20 to 50ft = Coil</li><li>• 51 to 170ft = 14 x 7in Reel</li><li>• 171 to 240ft = 14 x 10in Reel</li><li>• 241 to 370ft = 16 x 10in Reel</li><li>• 371 to 520ft = 18 x 10in Reel</li><li>• 521 to 675ft = 18 x 13in Reel</li><li>• 676 to 1505ft = 24 x 17in Wooden Reel</li><li>• 1506 to 2410ft = 30 x 17in Wooden Reel</li><li>• 2411 to 5000ft = Large Wooden Reel</li></ul>

## Agency Approvals

<b>UL Listed File #</b>	E46194
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	90458
<b>RoHS Status</b>	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>
<b>Other</b>	<a href="#">RoHS Statement</a>