


SJEOOW-18-4BK-1 Cut Sheet

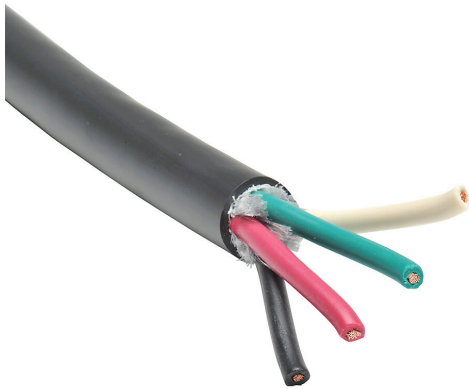

Southwire portable cord, unshielded, SJEOOW, 300V, 4 conductors (includes ground), 18 AWG, TPE conductor insulation material, black, white, red and green, TPE jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SJEOOW-18-4BK-1>

Technical Specifications

Brand	Southwire
Item	Cord
Wire/Cable Type	Portable
UL Wire/Cable Type	SJEOOW
Applicable Standards	UL 62
Application	General purpose
Flexibility	Flexible
Voltage Rating	300V
Conductors	4 conductors (includes ground)
Conductor Size	18 AWG
Conductor Stranding	16-stranded
Conductor Material	Bare copper
Conductor Insulation Material	TPE
Conductor Insulation Color	Black, white, red and green

Shielding	Unshielded
Jacket Material	TPE
Jacket Color	Black
Nominal Overall Cable Diameter	0.335in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 75ft = Coil• 76 to 345ft = 14 x 7in Reel• 346 to 495ft = 14 x 10in Reel• 496 to 760ft = 16 x 10in Reel• 761 to 1065ft = 18 x 10in Reel• 1066 to 1385ft = 18 x 13in Reel• 1386 to 3095ft = 24 x 17in Wooden Reel• 3096 to 4950ft = 30 x 17in Wooden Reel• 4951 to 5000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E46194
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	90458
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement