


SJOOW-10-4BK-1 Cut Sheet

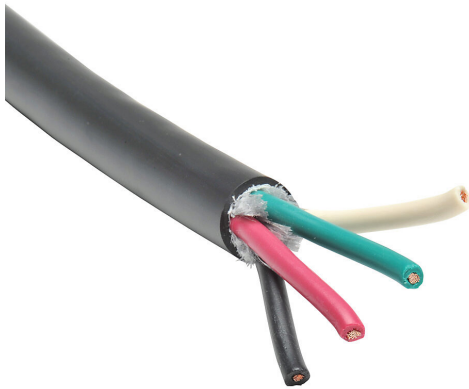

Southwire portable cord, unshielded, SJOOW, 300V, 4 conductors (includes ground), 10 AWG, EPDM thermoset rubber conductor insulation material, black, white, red and green, CPE thermoset rubber jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SJOOW-10-4BK-1>

Technical Specifications

Brand	Southwire	Conductor Insulation Color	Black, white, red and green
Item	Cord	Shielding	Unshielded
Wire/Cable Type	Portable	Jacket Material	CPE thermoset rubber
UL Wire/Cable Type	SJOOW	Jacket Color	Black
Applicable Standards	UL 62	Nominal Overall Cable Diameter	0.635in
Application	General purpose	Bulk Length	Cut to length
Flexibility	Flexible	Package Type	<ul style="list-style-type: none">• 20 to 50ft = Coil• 51 to 95ft = 14 x 7in Reel• 96 to 140ft = 14 x 10in Reel• 141 to 210ft = 16 x 10in Reel• 211 to 295ft = 18 x 10in Reel• 296 to 385ft = 18 x 13in Reel• 386 to 860ft = 24 x 17in Wooden Reel• 861 to 1000ft = 30 x 17in Wooden Reel
Voltage Rating	300V		
Conductors	4 conductors (includes ground)		
Conductor Size	10 AWG		
Conductor Stranding	104-stranded		
Conductor Material	Bare copper		
Conductor Insulation Material	EPDM thermoset rubber		

Agency Approvals

UL Listed File #	E46194
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	90458
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement