


# SJOOW-10-4BK-1 Cut Sheet

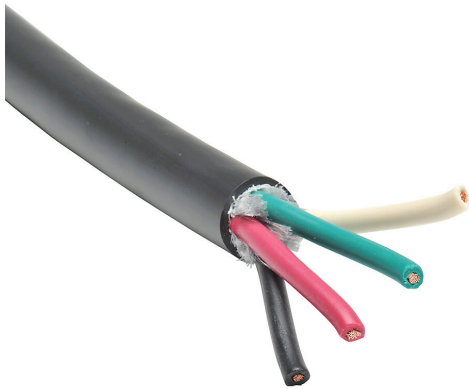

Southwire portable cord, unshielded, SJOOW, 300V, 4 conductors (includes ground), 10 AWG, EPDM thermoset rubber conductor insulation material, black, white, red and green, CPE thermoset rubber jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SJOOW-10-4BK-1>

## Technical Specifications

<b>Brand</b>	Southwire
<b>Item</b>	Cord
<b>Wire/Cable Type</b>	Portable
<b>UL Wire/Cable Type</b>	SJOOW
<b>Applicable Standards</b>	UL 62
<b>Application</b>	General purpose
<b>Flexibility</b>	Flexible
<b>Voltage Rating</b>	300V
<b>Conductors</b>	4 conductors (includes ground)
<b>Conductor Size</b>	10 AWG
<b>Conductor Stranding</b>	104-stranded
<b>Conductor Material</b>	Bare copper
<b>Conductor Insulation Material</b>	EPDM thermoset rubber
<b>Conductor Insulation Color</b>	Black, white, red and green

<b>Shielding</b>	Unshielded
<b>Jacket Material</b>	CPE thermoset rubber
<b>Jacket Color</b>	Black
<b>Nominal Overall Cable Diameter</b>	0.635in
<b>Bulk Length</b>	Cut to length
<b>Package Type</b>	1 to 50ft = Coil, 51 to 90ft = 14 x 7in Reel, 91 to 130ft = 14 x 10in Reel, 131 to 210ft = 16 x 10in Reel, 211 to 300ft = 18 x 10in Reel, 301 to 390ft = 18 x 13in Reel, 391 to 840ft = 24 x 17in Wooden Reel, 841 to 1380ft = 30 x 17in Wooden Reel, 1381 to MAX = Large Wooden Reel

## Agency Approvals

<b>UL Listed File #</b>	E46194
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	90458
<b>RoHS Status</b>	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>
<b>Other</b>	<a href="#">RoHS Statement</a>