


SJOOW-12-4BK-1 Cut Sheet

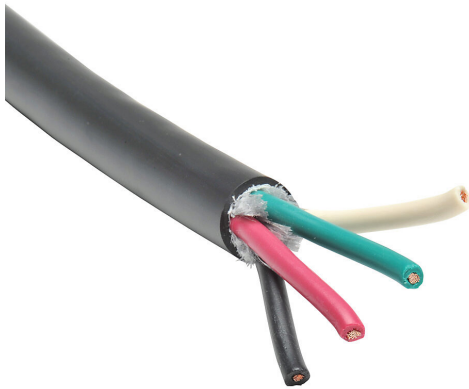

Southwire portable cord, unshielded, SJOOW, 300V, 4 conductors (includes ground), 12 AWG, EPDM thermoset rubber conductor insulation material, black, white, red and green, CPE thermoset rubber jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SJOOW-12-4BK-1>

Technical Specifications

Brand	Southwire
Item	Cord
Wire/Cable Type	Portable
UL Wire/Cable Type	SJOOW
Applicable Standards	UL 62
Application	General purpose
Flexibility	Flexible
Voltage Rating	300V
Conductors	4 conductors (includes ground)
Conductor Size	12 AWG
Conductor Stranding	65-stranded
Conductor Material	Bare copper
Conductor Insulation Material	EPDM thermoset rubber
Conductor Insulation Color	Black, white, red and green

Shielding	Unshielded
Jacket Material	CPE thermoset rubber
Jacket Color	Black
Nominal Overall Cable Diameter	0.47in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 50ft = Coil• 51 to 175ft = 14 x 7in Reel• 176 to 250ft = 14 x 10in Reel• 251 to 385ft = 16 x 10in Reel• 386 to 540ft = 18 x 10in Reel• 541 to 705ft = 18 x 13in Reel• 706 to 1570ft = 24 x 17in Wooden Reel• 1571 to 2515ft = 30 x 17in Wooden Reel• 2516 to 5000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E46194
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	90458
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement