


SJOOW-14-4BK-1 Cut Sheet

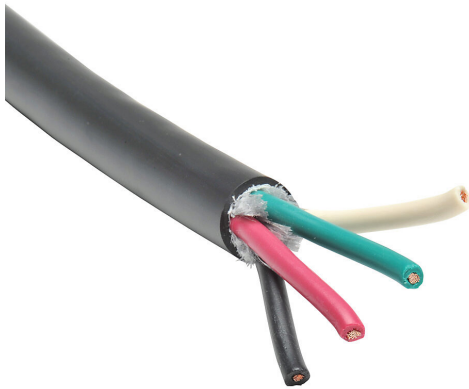

Southwire portable cord, unshielded, SJOOW, 300V, 4 conductors (includes ground), 14 AWG, EPDM thermoset rubber conductor insulation material, black, white, red and green, CPE thermoset rubber jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SJOOW-14-4BK-1>

Technical Specifications

Brand	Southwire	Shielding	Unshielded
Item	Cord	Jacket Material	CPE thermoset rubber
Wire/Cable Type	Portable	Jacket Color	Black
UL Wire/Cable Type	SJOOW	Nominal Overall Cable Diameter	0.395in
Applicable Standards	UL 62	Bulk Length	Cut to length
Application	General purpose	Package Type	1 to 50ft = Coil, 51 to 250ft = 14 x 7in Reel, 251 to 350ft = 14 x 10in Reel, 351 to 550ft = 16 x 10in Reel, 551 to 780ft = 18 x 10in Reel, 781 to 1010ft = 18 x 13in Reel, 1011 to 2180ft = 24 x 17in Wooden Reel, 2181 to 3590ft = 30 x 17in Wooden Reel, 3591 to MAX = Large Wooden Reel
Flexibility	Flexible		
Voltage Rating	300V		
Conductors	4 conductors (includes ground)		
Conductor Size	14 AWG		
Conductor Stranding	41-stranded		
Conductor Material	Bare copper		
Conductor Insulation Material	EPDM thermoset rubber		
Conductor Insulation Color	Black, white, red and green		

Agency Approvals

UL Listed File #	E46194
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	90458
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement