


# SJOOW-16-4BK-1 Cut Sheet

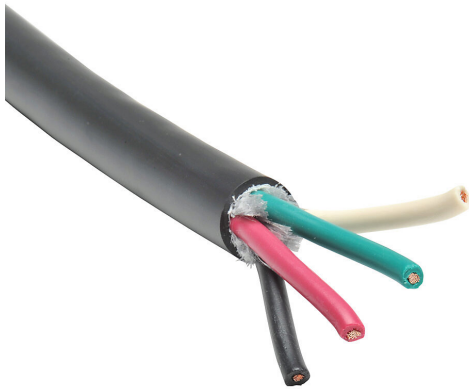

Southwire portable cord, unshielded, SJOOW, 300V, 4 conductors (includes ground), 16 AWG, EPDM thermoset rubber conductor insulation material, black, white, red and green, CPE thermoset rubber jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SJOOW-16-4BK-1>

## Technical Specifications

<b>Brand</b>	Southwire
<b>Item</b>	Cord
<b>Wire/Cable Type</b>	Portable
<b>UL Wire/Cable Type</b>	SJOOW
<b>Applicable Standards</b>	UL 62
<b>Application</b>	General purpose
<b>Flexibility</b>	Flexible
<b>Voltage Rating</b>	300V
<b>Conductors</b>	4 conductors (includes ground)
<b>Conductor Size</b>	16 AWG
<b>Conductor Stranding</b>	26-stranded
<b>Conductor Material</b>	Bare copper
<b>Conductor Insulation Material</b>	EPDM thermoset rubber
<b>Conductor Insulation Color</b>	Black, white, red and green

<b>Shielding</b>	Unshielded
<b>Jacket Material</b>	CPE thermoset rubber
<b>Jacket Color</b>	Black
<b>Nominal Overall Cable Diameter</b>	0.357in
<b>Bulk Length</b>	Cut to length
<b>Package Type</b>	1 to 75ft = Coil, 76 to 300ft = 14 x 7in Reel, 301 to 430ft = 14 x 10in Reel, 431 to 670ft = 16 x 10in Reel, 671 to 950ft = 18 x 10in Reel, 951 to 1240ft = 18 x 13in Reel, 1241 to 2670ft = 24 x 17in Wooden Reel, 2671 to 4390ft = 30 x 17in Wooden Reel, 4391 to MAX = Large Wooden Reel

## Agency Approvals

<b>UL Listed File #</b>	E46194
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	90458
<b>RoHS Status</b>	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>
<b>Other</b>	<a href="#">RoHS Statement</a>