


# SJOOW-18-3BK-1 Cut Sheet

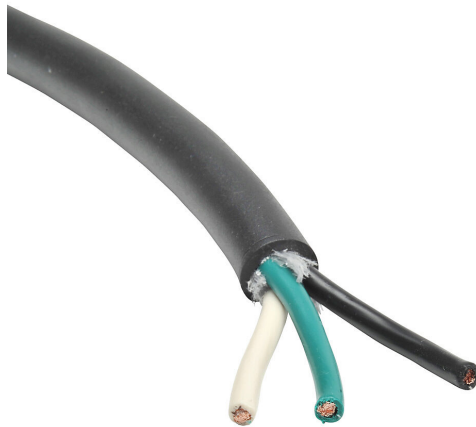

Southwire portable cord, unshielded, SJOOW, 300V, 3 conductors (includes ground), 18 AWG, EPDM thermoset rubber conductor insulation material, black, white and green, CPE thermoset rubber jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SJOOW-18-3BK-1>

## Technical Specifications

<b>Brand</b>	Southwire
<b>Item</b>	Cord
<b>Wire/Cable Type</b>	Portable
<b>UL Wire/Cable Type</b>	SJOOW
<b>Applicable Standards</b>	UL 62
<b>Application</b>	General purpose
<b>Flexibility</b>	Flexible
<b>Voltage Rating</b>	300V
<b>Conductors</b>	3 conductors (includes ground)
<b>Conductor Size</b>	18 AWG
<b>Conductor Stranding</b>	16-stranded
<b>Conductor Material</b>	Bare copper
<b>Conductor Insulation Material</b>	EPDM thermoset rubber

<b>Conductor Insulation Color</b>	Black, white and green
<b>Shielding</b>	Unshielded
<b>Jacket Material</b>	CPE thermoset rubber
<b>Jacket Color</b>	Black
<b>Nominal Overall Cable Diameter</b>	0.31in
<b>Bulk Length</b>	Cut to length
<b>Package Type</b>	<ul style="list-style-type: none"><li>• 20 to 99ft = Coil</li><li>• 100 to 405ft = 14 x 7in Reel</li><li>• 406 to 580ft = 14 x 10in Reel</li><li>• 581 to 890ft = 16 x 10in Reel</li><li>• 891 to 1240ft = 18 x 10in Reel</li><li>• 1241 to 1615ft = 18 x 13in Reel</li><li>• 1616 to 3615ft = 24 x 17in Wooden Reel</li><li>• 3616 to 5000ft = 30 x 17in Wooden Reel</li></ul>

## Agency Approvals

<b>UL Listed File #</b>	E46194
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	90458
<b>RoHS Status</b>	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>
<b>Other</b>	<a href="#">RoHS Statement</a>