


# SJOOW-18-4BK-1 Cut Sheet

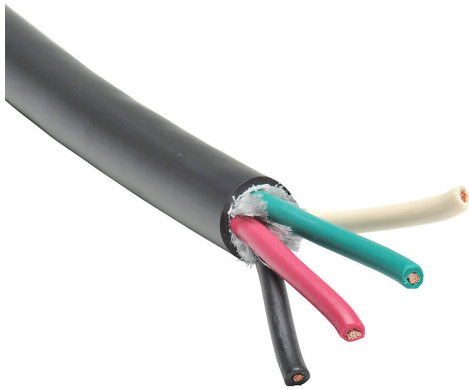

Southwire portable cord, unshielded, SJOOW, 300V, 4 conductors (includes ground), 18 AWG, EPDM thermoset rubber conductor insulation material, black, white, red and green, CPE thermoset rubber jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SJOOW-18-4BK-1>

## Technical Specifications

<b>Brand</b>	Southwire
<b>Item</b>	Cord
<b>Wire/Cable Type</b>	Portable
<b>UL Wire/Cable Type</b>	SJOOW
<b>Applicable Standards</b>	UL 62
<b>Application</b>	General purpose
<b>Flexibility</b>	Flexible
<b>Voltage Rating</b>	300V
<b>Conductors</b>	4 conductors (includes ground)
<b>Conductor Size</b>	18 AWG
<b>Conductor Stranding</b>	16-stranded
<b>Conductor Material</b>	Bare copper
<b>Conductor Insulation Material</b>	EPDM thermoset rubber
<b>Conductor Insulation Color</b>	Black, white, red and green

<b>Shielding</b>	Unshielded
<b>Jacket Material</b>	CPE thermoset rubber
<b>Jacket Color</b>	Black
<b>Nominal Overall Cable Diameter</b>	0.33in
<b>Bulk Length</b>	Cut to length
<b>Package Type</b>	1 to 75ft = Coil, 76 to 350ft = 14 x 7in Reel, 351 to 510ft = 14 x 10in Reel, 511 to 790ft = 16 x 10in Reel, 791 to 1120ft = 18 x 10in Reel, 1121 to 1450ft = 18 x 13in Reel, 1451 to 3120ft = 24 x 17in Wooden Reel, 3121 to 5140ft = 30 x 17in Wooden Reel, 5141 to MAX = Large Wooden Reel

## Agency Approvals

<b>UL Listed File #</b>	E46194
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	90458
<b>RoHS Status</b>	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>
<b>Other</b>	<a href="#">RoHS Statement</a>