


SJOOW-18-4BK-1 Cut Sheet

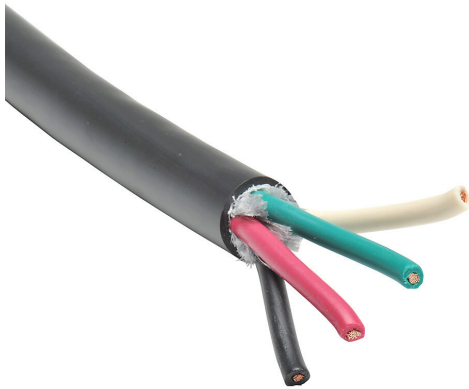

Southwire portable cord, unshielded, SJOOW, 300V, 4 conductors (includes ground), 18 AWG, EPDM thermoset rubber conductor insulation material, black, white, red and green, CPE thermoset rubber jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SJOOW-18-4BK-1>

Technical Specifications

Brand	Southwire
Item	Cord
Wire/Cable Type	Portable
UL Wire/Cable Type	SJOOW
Applicable Standards	UL 62
Application	General purpose
Flexibility	Flexible
Voltage Rating	300V
Conductors	4 conductors (includes ground)
Conductor Size	18 AWG
Conductor Stranding	16-stranded
Conductor Material	Bare copper
Conductor Insulation Material	EPDM thermoset rubber

Conductor Insulation Color	Black, white, red and green
Shielding	Unshielded
Jacket Material	CPE thermoset rubber
Jacket Color	Black
Nominal Overall Cable Diameter	0.33in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 75ft = Coil• 76 to 360ft = 14 x 7in Reel• 361 to 510ft = 14 x 10in Reel• 511 to 785ft = 16 x 10in Reel• 786 to 1095ft = 18 x 10in Reel• 1096 to 1425ft = 18 x 13in Reel• 1426 to 3190ft = 24 x 17in Wooden Reel• 3191 to 5000ft = 30 x 17in Wooden Reel

Agency Approvals

UL Listed File #	E46194
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	90458
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement