


SLU-35-1 Cut Sheet

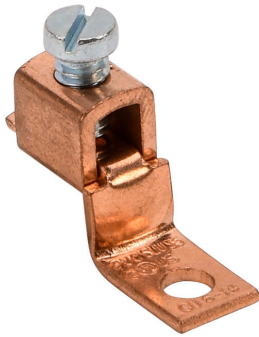

Penn-Union mechanical lug, offset tongue, copper-electrolytic, 35-50A, 1 openings, (1) 14 AWG solid-6 AWG stranded copper.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SLU-35-1>

Technical Specifications

Brand	Penn-Union
Item	Mechanical lug
Lug Type	Offset tongue
Material	Copper-electrolytic
Amperage Rating	35-50A
Number Of Openings	1
Tightening Torque	14-10 AWG 20 in-lb copper, 8 AWG 25 in-lb copper and 6 AWG 35 in-lb copper
Conductor Bolt Style	Slotted pan head
Conductor Material	Copper
Conductor Size	(1) 14 AWG solid-6 AWG stranded copper
Mounting Holes	1 hole
Mounting Bolt Size	#10

Agency Approvals

UL Listed File #	E12822, E73393
UL Recognized File #	None
UL Hazardous File #	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/SLU-35-1.pdf>
See store item page for other formats.