


SLU-70-1 Cut Sheet

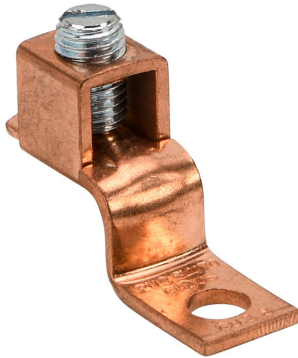

Penn-Union mechanical lug, offset tongue, copper-electrolytic, 70-90A, 1 openings, (1) 8 AWG solid-2 AWG stranded copper.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SLU-70-1>

Technical Specifications

Brand	Penn-Union
Item	Mechanical lug
Lug Type	Offset tongue
Material	Copper-electrolytic
Amperage Rating	70-90A
Number Of Openings	1
Tightening Torque	8 AWG 40 in-lb copper, 6-4 AWG 45 in-lb copper, 3 AWG 50 in-lb copper and 2 AWG 50 in-lb copper
Conductor Bolt Style	Slotted set screw
Conductor Material	Copper
Conductor Size	(1) 8 AWG solid-2 AWG stranded copper
Mounting Holes	1 hole
Mounting Bolt Size	1/4in

Agency Approvals

UL Listed File #	E12822, E73393
UL Recognized File #	None
UL Hazardous File #	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/SLU-70-1.pdf>
See store item page for other formats.