


# SOOW-10-5BK-1 Cut Sheet

Southwire portable cord, unshielded, SOOW, 600V, 5 conductors (includes ground), 10 AWG, EPDM thermoset rubber conductor insulation material, black, white, red, green and orange, CPE thermoset rubber jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SOOW-10-5BK-1>

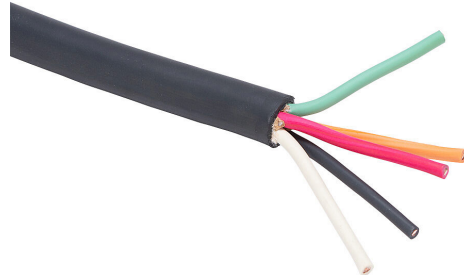

## Technical Specifications

<b>Brand</b>	Southwire
<b>Item</b>	Cord
<b>Wire/Cable Type</b>	Portable
<b>UL Wire/Cable Type</b>	SOOW
<b>Applicable Standards</b>	UL 62
<b>Application</b>	General purpose
<b>Flexibility</b>	Flexible
<b>Voltage Rating</b>	600V
<b>Conductors</b>	5 conductors (includes ground)
<b>Conductor Size</b>	10 AWG
<b>Conductor Stranding</b>	104-stranded
<b>Conductor Material</b>	Bare copper
<b>Conductor Insulation Material</b>	EPDM thermoset rubber
<b>Conductor Insulation Color</b>	Black, white, red, green and orange

<b>Shielding</b>	Unshielded
<b>Jacket Material</b>	CPE thermoset rubber
<b>Jacket Color</b>	Black
<b>Nominal Overall Cable Diameter</b>	0.77in
<b>Bulk Length</b>	Cut to length
<b>Package Type</b>	<ul style="list-style-type: none"><li>• 20 to 30ft = Coil</li><li>• 31 to 65ft = 14 x 7in Reel</li><li>• 66 to 95ft = 14 x 10in Reel</li><li>• 96 to 145ft = 16 x 10in Reel</li><li>• 146 to 200ft = 18 x 10in Reel</li><li>• 201 to 260ft = 18 x 13in Reel</li><li>• 261 to 585ft = 24 x 17in Wooden Reel</li><li>• 586 to 935ft = 30 x 17in Wooden Reel</li><li>• 936 to 1000ft = Large Wooden Reel</li></ul>

## Agency Approvals

<b>UL Listed File #</b>	E46194
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	90458
<b>RoHS Status</b>	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>
<b>Other</b>	<a href="#">RoHS Statement</a>