


# SOOW-12-5BK-1 Cut Sheet

Southwire portable cord, unshielded, SOOW, 600V, 5 conductors (includes ground), 12 AWG, EPDM thermoset rubber conductor insulation material, black, white, red, green and orange, CPE thermoset rubber jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SOOW-12-5BK-1>

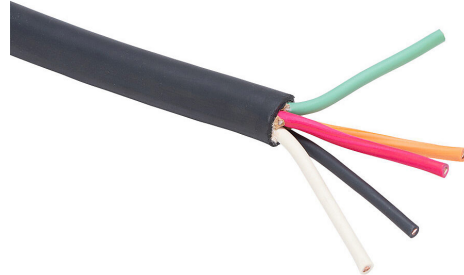

## Technical Specifications

<b>Brand</b>	Southwire
<b>Item</b>	Cord
<b>Wire/Cable Type</b>	Portable
<b>UL Wire/Cable Type</b>	SOOW
<b>Applicable Standards</b>	UL 62
<b>Application</b>	General purpose
<b>Flexibility</b>	Flexible
<b>Voltage Rating</b>	600V
<b>Conductors</b>	5 conductors (includes ground)
<b>Conductor Size</b>	12 AWG
<b>Conductor Stranding</b>	65-stranded
<b>Conductor Material</b>	Bare copper
<b>Conductor Insulation Material</b>	EPDM thermoset rubber

<b>Conductor Insulation Color</b>	Black, white, red, green and orange
<b>Shielding</b>	Unshielded
<b>Jacket Material</b>	CPE thermoset rubber
<b>Jacket Color</b>	Black
<b>Nominal Overall Cable Diameter</b>	0.71in
<b>Bulk Length</b>	Cut to length
<b>Package Type</b>	<ul style="list-style-type: none"><li>• 20 to 50ft = Coil</li><li>• 51 to 75ft = 14 x 7in Reel</li><li>• 76 to 110ft = 14 x 10in Reel</li><li>• 111 to 170ft = 16 x 10in Reel</li><li>• 171 to 235ft = 18 x 10in Reel</li><li>• 236 to 310ft = 18 x 13in Reel</li><li>• 311 to 690ft = 24 x 17in Wooden Reel</li><li>• 691 to 1000ft = 30 x 17in Wooden Reel</li></ul>

## Agency Approvals

<b>UL Listed File #</b>	E46194
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	90458
<b>RoHS Status</b>	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>
<b>Other</b>	<a href="#">RoHS Statement</a>