


SOOW-14-4BK-1 Cut Sheet

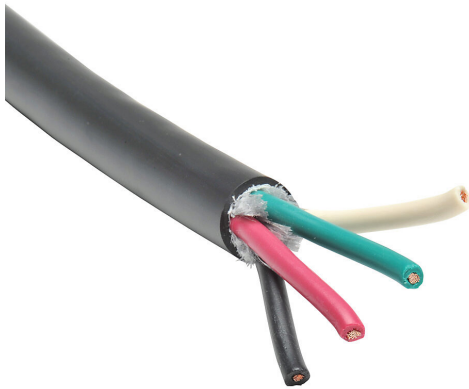

Southwire portable cord, unshielded, SOOW, 600V, 4 conductors (includes ground), 14 AWG, EPDM thermoset rubber conductor insulation material, black, white, red and green, CPE thermoset rubber jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SOOW-14-4BK-1>

Technical Specifications

Brand	Southwire
Item	Cord
Wire/Cable Type	Portable
UL Wire/Cable Type	SOOW
Applicable Standards	UL 62
Application	General purpose
Flexibility	Flexible
Voltage Rating	600V
Conductors	4 conductors (includes ground)
Conductor Size	14 AWG
Conductor Stranding	41-stranded
Conductor Material	Bare copper
Conductor Insulation Material	EPDM thermoset rubber
Conductor Insulation Color	Black, white, red and green

Shielding	Unshielded
Jacket Material	CPE thermoset rubber
Jacket Color	Black
Nominal Overall Cable Diameter	0.57in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 50ft = Coil• 51 to 120ft = 14 x 7in Reel• 121 to 170ft = 14 x 10in Reel• 171 to 265ft = 16 x 10in Reel• 266 to 365ft = 18 x 10in Reel• 366 to 480ft = 18 x 13in Reel• 481 to 1070ft = 24 x 17in Wooden Reel• 1071 to 1710ft = 30 x 17in Wooden Reel• 1711 to 5000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E46194
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	90458
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement