


SOOW-14-5BK-1 Cut Sheet

Southwire portable cord, unshielded, SOOW, 600V, 5 conductors (includes ground), 14 AWG, EPDM thermoset rubber conductor insulation material, black, white, red, green and orange, CPE thermoset rubber jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SOOW-14-5BK-1>

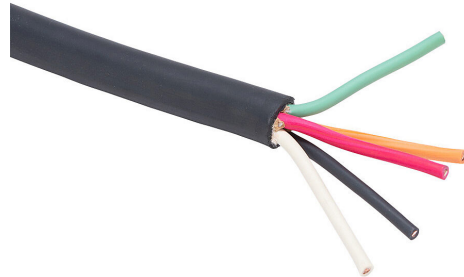

Technical Specifications

Brand	Southwire
Item	Cord
Wire/Cable Type	Portable
UL Wire/Cable Type	SOOW
Applicable Standards	UL 62
Application	General purpose
Flexibility	Flexible
Voltage Rating	600V
Conductors	5 conductors (includes ground)
Conductor Size	14 AWG
Conductor Stranding	41-stranded
Conductor Material	Bare copper
Conductor Insulation Material	EPDM thermoset rubber

Conductor Insulation Color	Black, white, red, green and orange
Shielding	Unshielded
Jacket Material	CPE thermoset rubber
Jacket Color	Black
Nominal Overall Cable Diameter	0.67in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 50ft = Coil• 51 to 85ft = 14 x 7in Reel• 86 to 125ft = 14 x 10in Reel• 126 to 190ft = 16 x 10in Reel• 191 to 265ft = 18 x 10in Reel• 266 to 345ft = 18 x 13in Reel• 346 to 775ft = 24 x 17in Wooden Reel• 776 to 1000ft = 30 x 17in Wooden Reel

Agency Approvals

UL Listed File #	E46194
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	90458
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement