


SOOW-16-4BK-1 Cut Sheet

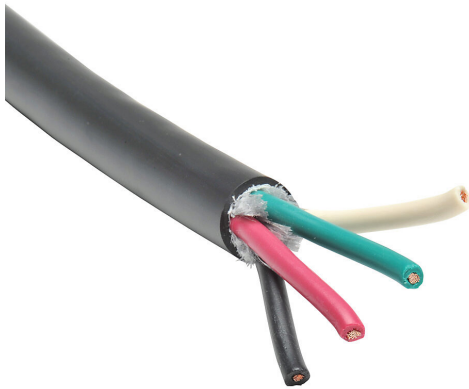

Southwire portable cord, unshielded, SOOW, 600V, 4 conductors (includes ground), 16 AWG, EPDM thermoset rubber conductor insulation material, black, white, red and green, CPE thermoset rubber jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SOOW-16-4BK-1>

Technical Specifications

Brand	Southwire
Item	Cord
Wire/Cable Type	Portable
UL Wire/Cable Type	SOOW
Applicable Standards	UL 62
Application	General purpose
Flexibility	Flexible
Voltage Rating	600V
Conductors	4 conductors (includes ground)
Conductor Size	16 AWG
Conductor Stranding	26-stranded
Conductor Material	Bare copper
Conductor Insulation Material	EPDM thermoset rubber
Conductor Insulation Color	Black, white, red and green

Shielding	Unshielded
Jacket Material	CPE thermoset rubber
Jacket Color	Black
Nominal Overall Cable Diameter	0.415in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 1 to 50ft = Coil• 51 to 220ft = 14 x 7in Reel• 221 to 320ft = 14 x 10in Reel• 321 to 500ft = 16 x 10in Reel• 501 to 700ft = 18 x 10in Reel• 701 to 920ft = 18 x 13in Reel• 921 to 1970ft = 24 x 17in Wooden Reel• 1971 to 3250ft = 30 x 17in Wooden Reel• 3251 to MAX = Large Wooden Reel

Agency Approvals

UL Listed File #	E46194
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	90458
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement