


SOOW-16-5BK-1 Cut Sheet

Southwire portable cord, unshielded, SOOW, 600V, 5 conductors (includes ground), 16 AWG, EPDM thermoset rubber conductor insulation material, black, white, red, green and orange, CPE thermoset rubber jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SOOW-16-5BK-1>

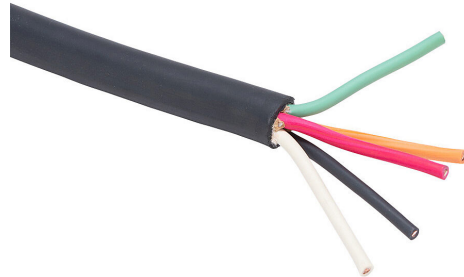

Technical Specifications

Brand	Southwire
Item	Cord
Wire/Cable Type	Portable
UL Wire/Cable Type	SOOW
Applicable Standards	UL 62
Application	General purpose
Flexibility	Flexible
Voltage Rating	600V
Conductors	5 conductors (includes ground)
Conductor Size	16 AWG
Conductor Stranding	26-stranded
Conductor Material	Bare copper
Conductor Insulation Material	EPDM thermoset rubber
Conductor Insulation Color	Black, white, red, green and orange

Shielding	Unshielded
Jacket Material	CPE thermoset rubber
Jacket Color	Black
Nominal Overall Cable Diameter	0.5in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 50ft = Coil• 51 to 155ft = 14 x 7in Reel• 156 to 225ft = 14 x 10in Reel• 226 to 340ft = 16 x 10in Reel• 341 to 475ft = 18 x 10in Reel• 476 to 620ft = 18 x 13in Reel• 621 to 1390ft = 24 x 17in Wooden Reel• 1391 to 2220ft = 30 x 17in Wooden Reel• 2221 to 5000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E46194
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	90458
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement