


SOOW-6-4BK-1 Cut Sheet

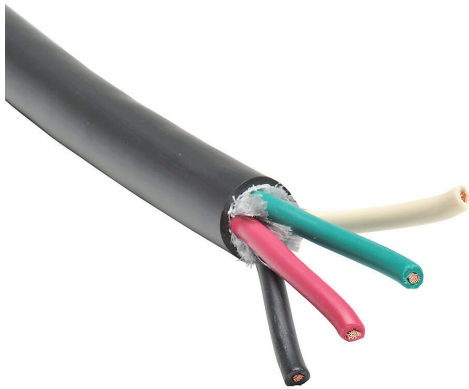

Direct Wire portable cord, unshielded, SOOW, 600V, 4 conductors (includes ground), 6 AWG, EPDM thermoset rubber conductor insulation material, black, white, red and green, CPE thermoset rubber jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SOOW-6-4BK-1>

Technical Specifications

Brand	Direct Wire
Item	Cord
Wire/Cable Type	Portable
UL Wire/Cable Type	SOOW
Application	Power
Flexibility	Flexible
Voltage Rating	600V
Conductors	4 conductors (includes ground)
Conductor Size	6 AWG
Conductor Stranding	260-stranded
Conductor Material	Bare copper
Conductor Insulation Material	EPDM thermoset rubber
Conductor Insulation Color	Black, white, red and green

Shielding	Unshielded
Jacket Material	CPE thermoset rubber
Jacket Color	Black
Nominal Overall Cable Diameter	0.835in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 10 to 30ft = Coil• 31 to 55ft = 14 x 7in Reel• 56 to 80ft = 14 x 10in Reel• 81 to 125ft = 16 x 10in Reel• 126 to 170ft = 18 x 10in Reel• 171 to 225ft = 18 x 13in Reel• 226 to 500ft = 24 x 17in Wooden Reel• 501 to 795ft = 30 x 17in Wooden Reel• 796 to 2500ft = Large Wooden Reel

Agency Approvals

UL Listed File #	none
UL Recognized File #	none
UL Hazardous File #	none
CSA File #	none
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement