


# SP50PR Cut Sheet

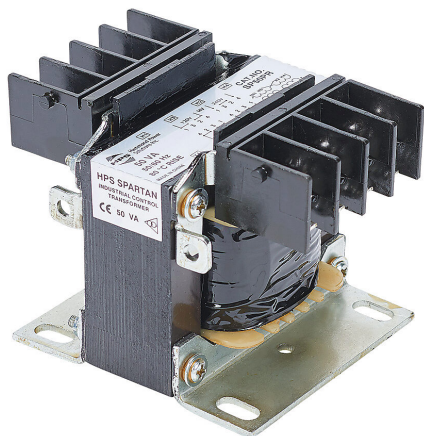

Hammond control transformer, open core, 50 VA, 1-phase, 120/240 VAC primary, 12/24 VAC secondary, 50/60 Hz, panel mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SP50PR>

## Technical Specifications

Brand	Hammond
Series	Spartan
Item	Transformer
Transformer Type	Control
Core Type	Open
Power Rating	50 VA
Number of Phases	1
Primary Voltage	120/240 VAC
Secondary Voltage	12/24 VAC
Frequency	50/60 Hz
Fused	No
Electrostatic Shield	No
Mounting	Panel
Connection	Screw terminal

## Agency Approvals

UL Listed File #	E50394
UL Recognized File #	None
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	LR 3902
RoHS Status	No
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/SP50PR.pdf>  
See store item page for other formats.