


SR35-PSU Cut Sheet

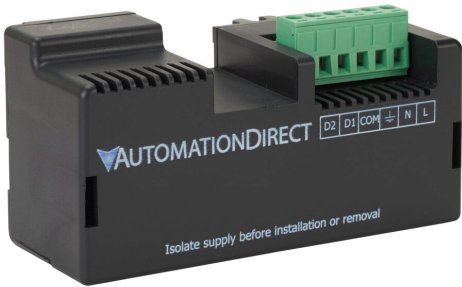

Stellar SR35 series switching power supply, 24 VDC @ 1A/120W (adjustable), 120/240 VAC nominal input, 1-phase, enclosed, plastic housing, direct mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/SR35-PSU>

Technical Specifications

Brand	Stellar
Item	Power supply
Series	SR35
Power Supply Type	Switching
Output Configuration	Single output
Output	24 VDC @ 1A/120W (adjustable)
Output Voltage Range	24 VDC
Input voltage range	120/240 VAC
Input Voltage Selection Type	Automatic
Number of Input Phases	1

Protection Type(s)	fused overcurrent
Remote On/Off	No
Voltage Monitoring	No
Enclosure Type	Enclosed
Housing Material	Plastic
Mounting	Direct
NEC Class 2	No
Integrated UPS Battery Control	No
For Use With	SR35 series soft starters

Agency Approvals

UL Listed File #	E333109
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/SR35-PSU.pdf>
See store item page for other formats.