


T2L-ND-41-240U Cut Sheet

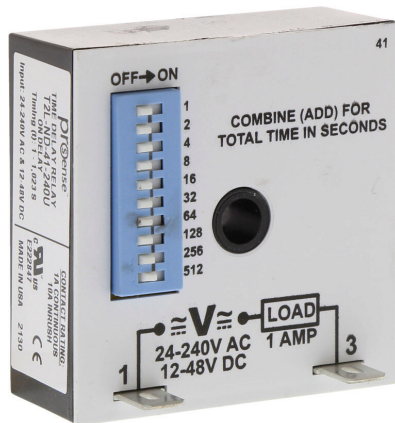

ProSense on-delay inline relay timer, 1 to 1,023 seconds selectable timing range, 24-240 VAC and 12-48 VDC operating voltage, 1A contact rating, (1) SPNO timed solid state relay output(s), surface mount, 1/4in male quick-connect terminal.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/T2L-ND-41-240U>

Technical Specifications

Brand	ProSense
Item	Inline relay timer
Timer Type	On-delay
Timing Range	1 to 1,023 seconds selectable
Operating Voltage	24-240 VAC and 12-48 VDC
Timer Output Type(s)	(1) SPNO timed solid state relay
Timer Function(s)	on-delay
Contact Rating	1A
Mounting	Surface
Connector Type	1/4in male quick-connect terminal

Agency Approvals

UL Listed File #	None
UL Recognized File #	E222847
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document