


# T30-50500-6C Cut Sheet

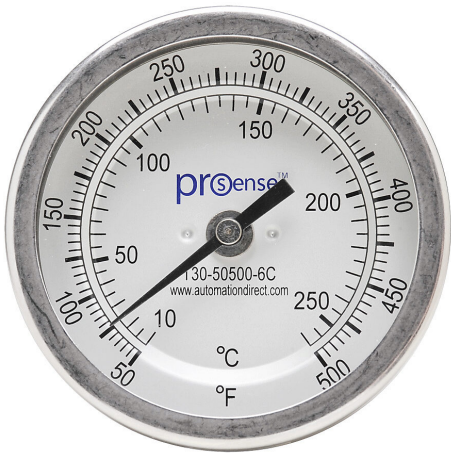

ProSense bi-metal dial thermometer, 3in diameter, 6in insertion length, 50 to 500 deg F/10 to 260 deg C, 1/2in male NPT process connection, center back mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/T30-50500-6C>

## Technical Specifications

Brand	ProSense
Item	Bi-metal dial thermometer
Diameter	3in
Insertion Length	6in
Scale	50 to 500 deg F/10 to 260 deg C
Process Connection	1/2in male NPT
Mounting	Center back

## Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/T30-50500-6C.pdf>  
See store item page for other formats.