


# T60030-2SR Cut Sheet

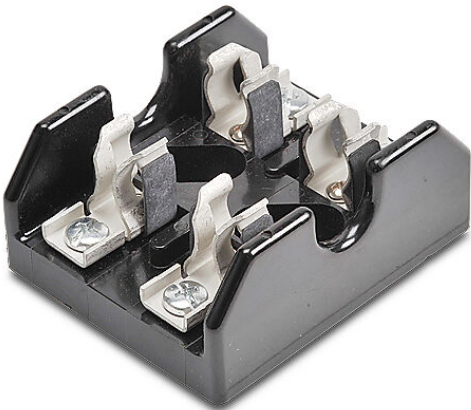

Bussmann fuse block, accepts T fuses, 30A, 600V, 2-pole, 18-10 AWG copper only, screw with pressure plate, panel mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/T60030-2SR>

## Technical Specifications

Brand	Bussmann
Item	Fuse block
Modular	No
Blown Fuse Indicator	No
Multi-Wire	No
Accepts Fuse Class	T
Amperage Rating	30A
Voltage Rating	600V

Number of Poles	2
Conductor Size	18-10 AWG copper only
Conductor Connection Type	Screw with pressure plate
SCCR Rating	200kA SCCR
Fuse Connection Type	Clip with reinforced spring
Mounting	Panel

## Agency Approvals

UL Listed File #	E14853
UL Recognized File #	None
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	47235
RoHS Status	No
EU REACH	<a href="#">View EU REACH document</a>
Other	None

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/T60030-2SR.pdf>  
See store item page for other formats.