


THMJ-A01L04-01 Cut Sheet

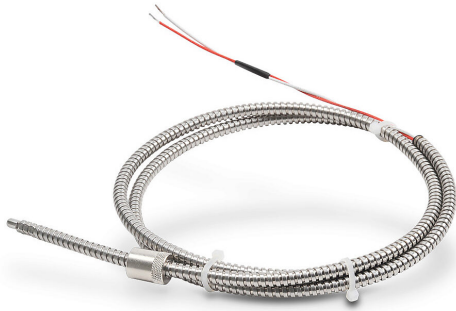

ProSense temperature sensor, Type J thermocouple, armor adjustable immersion probe, grounded, 1/4in insertion length, 3/16in probe diameter, stainless steel sheath, bayonet cap process connection, 4ft 20 AWG wire leads.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/THMJ-A01L04-01>

Technical Specifications

| | |
|--------------------------------------|------------------------------------|
| Brand | ProSense |
| Item | Temperature sensor |
| Sensor Element | Type J thermocouple |
| Sensor Type | Armor adjustable immersion probe |
| Accuracy | Standard limits of error |
| Junction Type | Grounded |
| Insertion Length | 1/4in |
| Probe Diameter | 3/16in |
| Sheath Material | Stainless steel |
| Process Connection | Bayonet cap |
| Bayonet Cap | 7/16in inside diameter single slot |
| Electrical Connection | 4ft 20 AWG wire leads |
| Conductor Insulation Material | Fiberglass and flexible armor |
| Temperature Sensing Range | 32 to 900 deg F |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | None |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | None |
| CSA File # | None |
| RoHS Status | No |
| EU REACH | View EU REACH document |