


# THMJ-B01L06-01 Cut Sheet

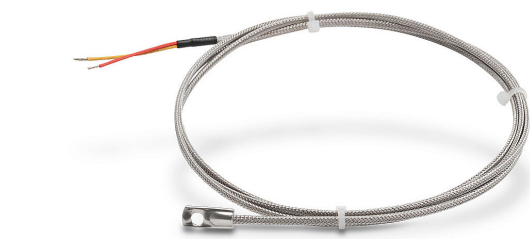

ProSense temperature sensor, Type J thermocouple, bolt-on ring, grounded junction, stainless steel sheath, #6 - #10 (4-5mm) screw or bolt size process connection, 6ft 20 AWG wire leads.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/THMJ-B01L06-01>

## Technical Specifications

Brand	ProSense
Item	Temperature sensor
Sensor Element	Type J thermocouple
Sensor Type	Bolt-on ring
Accuracy	Standard limits of error
Junction Type	Grounded
Sheath Material	Stainless steel
Process Connection	#6 - #10 (4-5mm) screw or bolt size
Electrical Connection	6ft 20 AWG wire leads
Conductor Insulation Material	Closed cell sponge rubber
Temperature Sensing Range	32 to 900 deg F

## Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/THMJ-B01L06-01.pdf>  
See store item page for other formats.