


THMJ-S02L06-01 Cut Sheet

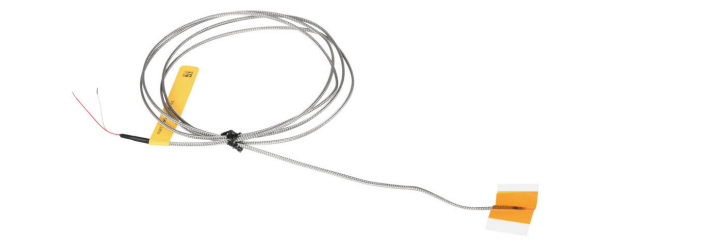

ProSense temperature sensor, Type J thermocouple, spade sensor, ungrounded junction, flexible polyimide with adhesive tape backing, 6ft 24 AWG wire leads.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/THMJ-S02L06-01>

Technical Specifications

Brand	ProSense
Item	Temperature sensor
Sensor Element	Type J thermocouple
Sensor Type	Spade sensor
Accuracy	Standard limits of error
Junction Type	Ungrounded
Spade Material	Flexible polyimide with adhesive tape backing
Sensor Insulation	Fiberglass
Electrical Connection	6ft 24 AWG wire leads
Conductor Insulation Material	Fiberglass and stainless steel overbraid
Temperature Sensing Range	0 to 400 deg F

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/THMJ-S02L06-01.pdf>
See store item page for other formats.