


THMK-B01L06-02 Cut Sheet

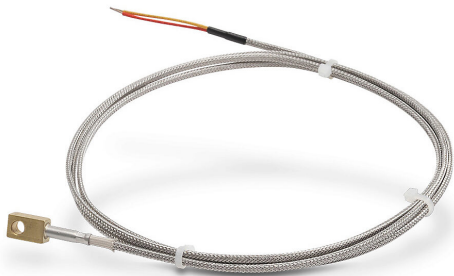

ProSense temperature sensor, Type K thermocouple, bolt-on ring, ungrounded junction, brass sheath, #6 - #10 (4-5mm) screw or bolt size process connection, 6ft 20 AWG wire leads.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/THMK-B01L06-02>

Technical Specifications

Brand	ProSense
Item	Temperature sensor
Sensor Element	Type K thermocouple
Sensor Type	Bolt-on ring
Accuracy	Standard limits of error
Junction Type	Ungrounded
Sheath Material	Brass
Process Connection	#6 - #10 (4-5mm) screw or bolt size
Electrical Connection	6ft 20 AWG wire leads
Conductor Insulation Material	Closed cell sponge rubber
Temperature Sensing Range	32 to 900 deg F

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/THMK-B01L06-02.pdf>
See store item page for other formats.