


THMK-C06-02 Cut Sheet

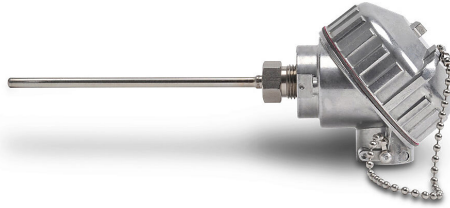

ProSense temperature sensor, Type K thermocouple, connection head probe, ungrounded, 6in insertion length, 1/4in probe diameter, stainless steel sheath, aluminum screw cover head with terminals.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/THMK-C06-02>

Technical Specifications

| | |
|-------------------------|----------------------------------------------|
| Brand | ProSense |
| Item | Temperature sensor |
| Sensor Element | Type K thermocouple |
| Sensor Type | Connection head probe |
| Media Type | Liquid, water, oil, chemicals, gases and air |
| Accuracy | Standard limits of error |
| Junction Type | Ungrounded |
| Insertion Length | 6in |

| | |
|----------------------------------|------------------------------------------|
| Probe Diameter | 1/4in |
| Sheath Material | Stainless steel |
| Sensor Insulation | Magnesium oxide (MgO) |
| Electrical Connection | Aluminum screw cover head with terminals |
| Temperature Sensing Range | 32 to 1700 deg F |
| IP Rating | IP66 |
| NEMA Rating | 4X |
| Additional Information | Purchase mounting fitting separately |

Agency Approvals

| | |
|-----------------------------|----------------------------------------|
| UL Listed File # | None |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | None |
| CSA File # | None |
| RoHS Status | No |
| EU REACH | View EU REACH document |

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/THMK-C06-02.pdf>
See store item page for other formats.