


# THMT-T06L06-01 Cut Sheet

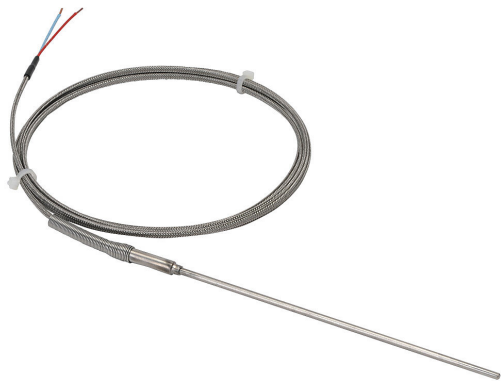

ProSense temperature sensor, Type T thermocouple, lead wire transition probe, ungrounded, 6in insertion length, 1/8in probe diameter, stainless steel sheath, 6ft 20 AWG wire leads.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/THMT-T06L06-01>

## Technical Specifications

Brand	ProSense
Item	Temperature sensor
Sensor Element	Type T thermocouple
Sensor Type	Lead wire transition probe
Accuracy	Standard limits of error
Junction Type	Ungrounded
Insertion Length	6in
Probe Diameter	1/8in
Sheath Material	Stainless steel
Sensor Insulation	Magnesium oxide (MgO)
Electrical Connection	6ft 20 AWG wire leads
Conductor Insulation Material	Fiberglass and stainless steel overbraid
Temperature Sensing Range	-328 to 700 deg F
Additional Information	Purchase mounting fitting separately

## Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	<a href="#">View EU REACH document</a>