


THMT-T12L06-01 Cut Sheet

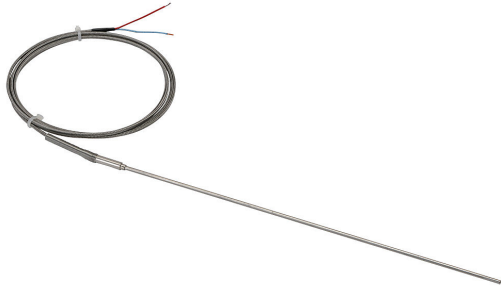

ProSense temperature sensor, Type T thermocouple, lead wire transition probe, ungrounded, 12in insertion length, 1/8in probe diameter, stainless steel sheath, 6ft 20 AWG wire leads.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/THMT-T12L06-01>

Technical Specifications

Brand	ProSense
Item	Temperature sensor
Sensor Element	Type T thermocouple
Sensor Type	Lead wire transition probe
Media Type	Liquid, water, oil, chemicals, gases and air
Accuracy	Standard limits of error
Junction Type	Ungrounded
Insertion Length	12in

Probe Diameter	1/8in
Sheath Material	Stainless steel
Sensor Insulation	Magnesium oxide (MgO)
Electrical Connection	6ft 20 AWG wire leads
Conductor Insulation Material	Closed cell sponge rubber
Temperature Sensing Range	-328 to 700 deg F
Additional Information	Purchase mounting fitting separately

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/THMT-T12L06-01.pdf>
See store item page for other formats.