


THMWK-20-1U-F-1 Cut Sheet

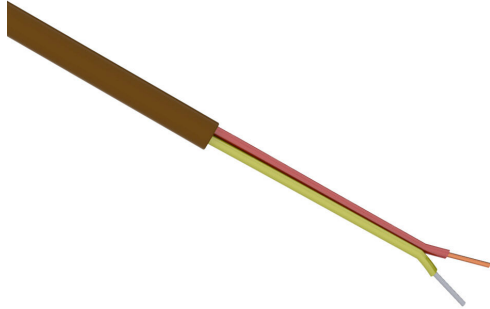

TE Wire & Cable Type K thermocouple extension wire, unshielded, 2 conductors, 20 AWG, nickel-chromium and nickel-aluminum, FEP Teflon conductor insulation material, yellow and red, FEP Teflon jacket, brown, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/THMWK-20-1U-F-1>

Technical Specifications

Brand	TE Wire & Cable
Item	Wire
Sensor Type	Type K thermocouple
Wire/Cable Type	Extension
Application	Temperature
Flexibility	Semi-flexible
Conductors	2 conductors
Conductor Size	20 AWG
Conductor Stranding	Solid
Conductor Material	Nickel-chromium and nickel-aluminum
Conductor Insulation Material	FEP Teflon
Conductor Insulation Color	Yellow and red
Shielding	Unshielded
Jacket Material	FEP Teflon
Jacket Color	Brown
Nominal Overall Cable Diameter	0.116in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 1 to 99ft = Coil• 100 to 2900ft =14 x 7in Reel• 2901 to 4140ft =14 x 10in Reel• 4141 to 5000ft = 16 x 10in Reel

Agency Approvals

UL Listed File #	none
UL Recognized File #	none
UL Hazardous File #	none
CSA File #	none
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement