


TK-E02-1100 Cut Sheet

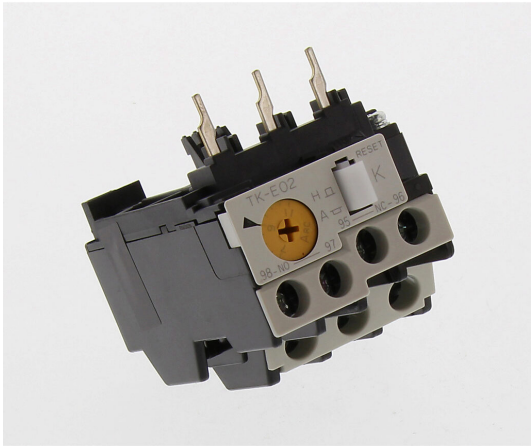

Fuji Electric TK-E02 series thermal overload relay, 7.0–11.0A adjustable, bi-metallic, local reset, direct mount power connection(s). For use with SC-E02x, SC-E03x, SC-E04x and SC-E05x series contactors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/TK-E02-1100>

Technical Specifications

Brand	Fuji Electric	Reset	Local
Item	Relay	Phase Loss Sensitive	Yes
Series	TK-E02	Ground Fault Protection	No
Relay Type	Thermal overload	Connection	Direct mount power
Full Load Amperage Range	7.0–11.0A adjustable	For Use With	SC-E02x, SC-E03x, SC-E04x and SC-E05x series contactors
Operation Type	Bi-metallic	Includes	(1) N.O. and (1) N.C. auxiliary contact
Auxiliary Contacts	(1) N.O. / (1) N.C.		
Trip Class	Trip Class 10A		

Agency Approvals

UL Listed File #	None
UL Recognized File #	E44592
UL Hazardous File #	None
CE	View CE declarations
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document