


TK-E02-36 Cut Sheet

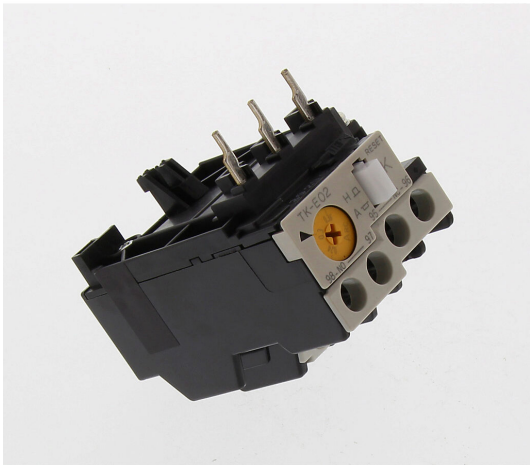

Fuji Electric TK-E02 series thermal overload relay, 0.24–0.36A adjustable, bi-metallic, local reset, direct mount power connection(s). For use with SC-E02x, SC-E03x, SC-E04x and SC-E05x series contactors.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/TK-E02-36>

Technical Specifications

Brand	Fuji Electric
Item	Relay
Series	TK-E02
Relay Type	Thermal overload
Full Load Amperage Range	0.24–0.36A adjustable
Operation Type	Bi-metallic
Auxiliary Contacts	(1) N.O. / (1) N.C.
Trip Class	Trip Class 10A

Reset	Local
Phase Loss Sensitive	Yes
Ground Fault Protection	No
Connection	Direct mount power
For Use With	SC-E02x, SC-E03x, SC-E04x and SC-E05x series contactors
Includes	(1) N.O. and (1) N.C. auxiliary contact

Agency Approvals

UL Listed File #	None
UL Recognized File #	E44592
UL Hazardous File #	None
CE	View CE declarations
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document