


# TRM-16-D-120AD Cut Sheet

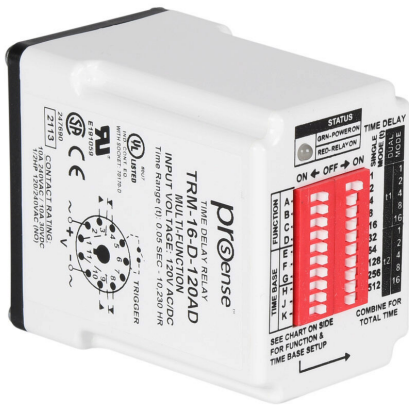

ProSense multi-mode relay timer, 0.05 seconds to 10,230 hours selectable timing range, 120 VAC/VDC operating voltage, 10A contact rating, (1) DPDT timed relay output(s), socket mount, 11-pin. Requires Macromatic 70170-D relay socket.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/TRM-16-D-120AD>

## Technical Specifications

Brand	ProSense	Contact Rating	10A
Item	Relay timer	Mounting	Socket
Timer Type	Multi-mode	Connector Type	11-pin
Indicator	LED	Requires	Macromatic 70170-D relay socket
Timing Range	0.05 seconds to 10,230 hours selectable		
Operating Voltage	120 VAC/VDC		
Timer Output Type(s)	(1) DPDT timed relay		
Timer Function(s)	<ul style="list-style-type: none"><li>• on-delay</li><li>• triggered on-delay</li><li>• off-delay</li><li>• on/off delay</li><li>• on-interval</li><li>• flasher (single-shot)</li><li>• on-flasher</li><li>• on-delay/flasher</li><li>• off-flasher</li><li>• watchdog</li><li>• single-shot</li><li>• falling edge (single-shot)</li><li>• on-cycle</li><li>• off-cycle</li><li>• delayed interval</li><li>• triggered delayed interval</li></ul>		

## Agency Approvals

UL Listed File #	E191059
UL Recognized File #	E191059
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	602618
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/TRM-16-D-120AD.pdf>  
See store item page for other formats.