


USTE100/2X115 Cut Sheet

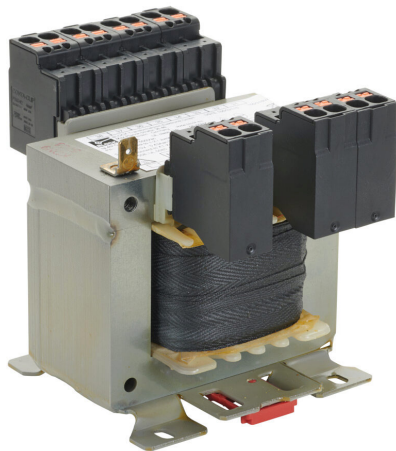

BLOCK control transformer, open core, 100 VA, 1-phase, 208-600 VAC selectable, 115/230 VAC secondary, 50/60 Hz, panel or 35mm DIN rail mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/USTE100/2X115>

Technical Specifications

| | |
|-------------------------------|---|
| Brand | BLOCK |
| Series | USTE |
| Item | Transformer |
| Transformer Type | Control |
| Core Type | Open |
| Power Rating | 100 VA |
| Number of Phases | 1 |
| Primary Voltage | 208/230/380/400/415/440/460/ 480/500/525/550/575/600 VAC |
| Secondary Voltage | 115/230 VAC |
| Frequency | 50/60 Hz |
| Fused | No |
| Electrostatic Shield | No |
| Mounting | Panel or 35mm DIN rail |
| Connection | Push-in terminal |
| Additional Information | Voltage selection jumpers sold separately |

Agency Approvals

| | |
|-------------------------|--|
| UL Listed File # | E103521 |
| CE | View CE declarations |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |

Dimensional Drawings



2D Drawing PDF Link:
[https://cdn.automationdirect.com/
/static/drawings/2d/USTE100_2X115.pdf](https://cdn.automationdirect.com/static/drawings/2d/USTE100_2X115.pdf)
See store item page for other formats.