


UV12GRN100 Cut Sheet

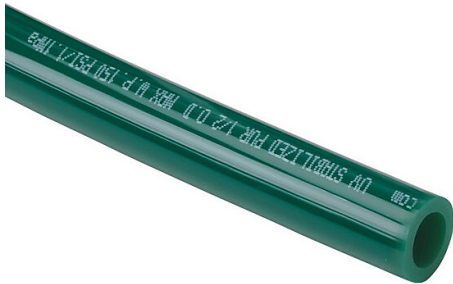

NITRA pneumatic tubing, ether-based polyurethane, dark green, 1/2in outside diameter, 0.328in inside diameter, UV stabilized, 100ft package.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/UV12GRN100>

Technical Specifications

Brand	NITRA
Item	Tubing
Working Fluid	Air or inert gas
Material	Ether-based polyurethane
Color	Dark green
Outside Diameter	1/2in
Inside Diameter	0.328in
UV stabilized	Yes
Working Length	100ft package
Operating Pressure	150 psi
Operating Temperature	-40 to +160 deg F

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document