


UV6MGRN500 Cut Sheet

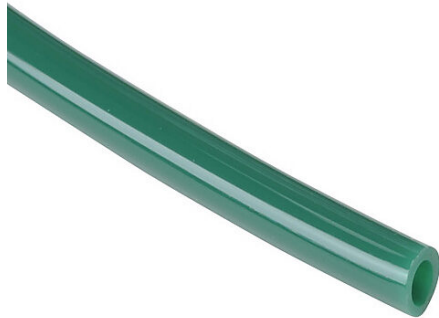

NITRA pneumatic tubing, ether-based polyurethane, dark green, 6mm outside diameter, 5/32in (4mm) inside diameter, UV stabilized, 500ft reel.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/UV6MGRN500>

Technical Specifications

| | |
|------------------------------|--------------------------|
| Brand | NITRA |
| Item | Pneumatic Tubing |
| Material | Ether-based polyurethane |
| Color | Dark green |
| Outside Diameter | 6mm |
| Inside Diameter | 5/32in (4mm) |
| UV stabilized | Yes |
| Working Length | 500ft reel |
| Operating Pressure | 180 psi |
| Operating Temperature | -40 to +160 deg F |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | None |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | None |
| CSA File # | None |
| RoHS Status | No |
| EU REACH | View EU REACH document |