


V30162-1 Cut Sheet

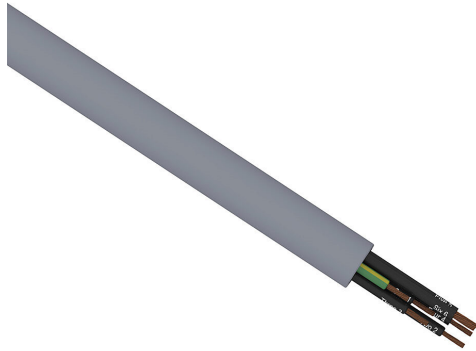

Southwire flexible control cable, unshielded, 7 conductors (includes ground), 20 AWG, bare copper, PVC/Nylon conductor insulation material, black with white numbers and green/yellow ground, TPE jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/V30162-1>

Technical Specifications

Brand	Southwire
Item	Cable
Wire/Cable Type	Control
UL Wire/Cable Type	PLTC-ER, ITC-ER and MTW
Application	General purpose
Flexibility	Flexible
Voltage Rating	300V (Types PLTC-ER, ITC-ER), 600V (Type MTW)
Conductors	7 conductors (includes ground)
Conductor Size	20 AWG
Conductor Stranding	10-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC/Nylon
Conductor Insulation Color	Black with white numbers and green/yellow ground

Shielding	Unshielded
Jacket Material	TPE
Jacket Color	Gray
Nominal Overall Cable Diameter	0.331in
Bulk Length	Cut to length
Package Type	1 to 75ft = Coil, 76 to 350ft = 14 x 7in Reel, 351 to 510ft = 14 x 10in Reel, 511 to 790ft = 16 x 10in Reel, 791 to 1110ft = 18 x 10in Reel, 1111 to 1440ft = 18 x 13in Reel, 1441 to 3100ft = 24 x 17in Wooden Reel, 3101 to 5110ft = 30 x 17in Wooden Reel, 5111 to MAX = Large Wooden Reel

Agency Approvals

UL Listed File #	E57497
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	90458
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement