


# V40166-1 Cut Sheet

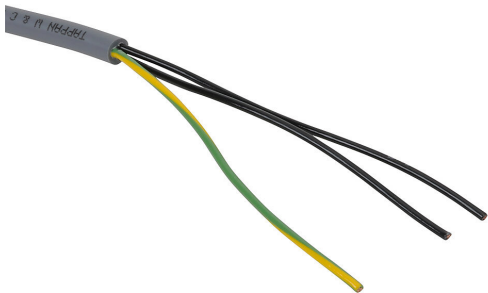

Southwire flexible control cable, unshielded, 3 conductors (includes ground), 18 AWG, bare copper, PVC/Nylon conductor insulation material, black with white numbers and green/yellow ground, TPE jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/V40166-1>

## Technical Specifications

Brand	Southwire	Conductor Insulation Color	Black with white numbers and green/yellow ground
Item	Cable	Shielding	Unshielded
Wire/Cable Type	Control	Jacket Material	TPE
UL Wire/Cable Type	TC, TC-ER, WTTC and MTW	Jacket Color	Gray
Applicable Standards	ECOLAB	Nominal Overall Cable Diameter	0.28in
Application	General purpose	Bulk Length	Cut to length
Flexibility	Flexible	Package Type	<ul style="list-style-type: none"><li>• 20 to 99ft = Coil</li><li>• 100 to 495ft = 14 x 7in Reel</li><li>• 496 to 710ft = 14 x 10in Reel</li><li>• 711 to 1090ft = 16 x 10in Reel</li><li>• 1091 to 1525ft = 18 x 10in Reel</li><li>• 1526 to 1980ft = 18 x 13in Reel</li><li>• 1981 to 4430ft = 24 x 17in Wooden Reel</li><li>• 4431 to 5000ft = 30 x 17in Wooden Reel</li></ul>
Voltage Rating	600V (Types TC, TC-ER, MTW), 1000V (Type WTTC)		
Conductors	3 conductors (includes ground)		
Conductor Size	18 AWG		
Conductor Stranding	16-stranded		
Conductor Material	Bare copper		
Conductor Insulation Material	PVC/Nylon		

## Agency Approvals

UL Listed File #	E75755
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	90458
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	<a href="#">View EU REACH document</a>
Other	<a href="#">RoHS Statement</a>