


# V40174-1 Cut Sheet

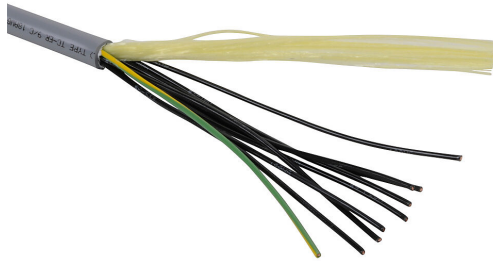

Southwire flexible control cable, unshielded, 9 conductors (includes ground), 18 AWG, bare copper, PVC/Nylon conductor insulation material, black with white numbers and green/yellow ground, TPE jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/V40174-1>

## Technical Specifications

<b>Brand</b>	Southwire	<b>Shielding</b>	Unshielded
<b>Item</b>	Cable	<b>Jacket Material</b>	TPE
<b>Wire/Cable Type</b>	Control	<b>Jacket Color</b>	Gray
<b>UL Wire/Cable Type</b>	TC, TC-ER, WTTC and MTW	<b>Nominal Overall Cable Diameter</b>	0.39in
<b>Applicable Standards</b>	ECOLAB	<b>Bulk Length</b>	Cut to length
<b>Application</b>	General purpose	<b>Package Type</b>	• 20 to 50ft = Coil
<b>Flexibility</b>	Flexible		• 51 to 255ft = 14 x 7in Reel
<b>Voltage Rating</b>	600V (Types TC, TC-ER, MTW), 1000V (Type WTTC)		• 256 to 365ft = 14 x 10in Reel
<b>Conductors</b>	9 conductors (includes ground)		• 366 to 560ft = 16 x 10in Reel
<b>Conductor Size</b>	18 AWG		• 561 to 785ft = 18 x 10in Reel
<b>Conductor Stranding</b>	16-stranded		• 786 to 1020ft = 18 x 13in Reel
<b>Conductor Material</b>	Bare copper		• 1021 to 2285ft = 24 x 17in Wooden Reel
<b>Conductor Insulation Material</b>	PVC/Nylon		• 2286 to 3655ft = 30 x 17in Wooden Reel
<b>Conductor Insulation Color</b>	Black with white numbers and green/yellow ground		• 3656 to 5000ft = Large Wooden Reel

## Agency Approvals

<b>UL Listed File #</b>	E75755
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	90458
<b>RoHS Status</b>	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>
<b>Other</b>	<a href="#">RoHS Statement</a>