


V50214-1 Cut Sheet

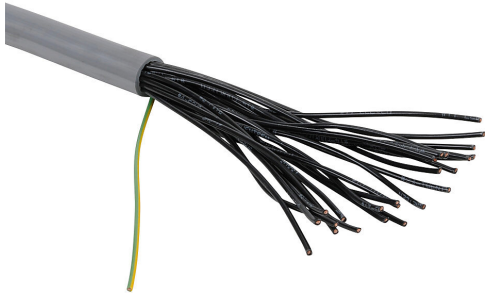

Southwire flexible control cable, unshielded, 25 conductors (includes ground), 16 AWG, bare copper, PVC/Nylon conductor insulation material, black with white numbers and green/yellow ground, TPE jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/V50214-1>

Technical Specifications

Brand	Southwire	Shielding	Unshielded
Item	Cable	Jacket Material	TPE
Wire/Cable Type	Control	Jacket Color	Gray
UL Wire/Cable Type	TC, TC-ER, WTTTC and MTW	Nominal Overall Cable Diameter	0.68in
Applicable Standards	ECOLAB	Bulk Length	Cut to length
Application	General purpose	Package Type	<ul style="list-style-type: none">• 20 to 50ft = Coil• 51 to 85ft = 14 x 7in Reel• 86 to 120ft = 14 x 10in Reel• 121 to 185ft = 16 x 10in Reel• 186 to 260ft = 18 x 10in Reel• 261 to 335ft = 18 x 13in Reel• 336 to 750ft = 24 x 17in Wooden Reel• 751 to 1200ft = 30 x 17in Wooden Reel• 1201 to 2500ft = Large Wooden Reel
Flexibility	Flexible		
Voltage Rating	600V (Types TC, TC-ER, MTW), 1000V (Type WTTTC)		
Conductors	25 conductors (includes ground)		
Conductor Size	16 AWG		
Conductor Stranding	26-stranded		
Conductor Material	Bare copper		
Conductor Insulation Material	PVC/Nylon		
Conductor Insulation Color	Black with white numbers and green/yellow ground		

Agency Approvals

UL Listed File #	E75755
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	90458
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement