


VNTC-12-3-BK-1 Cut Sheet

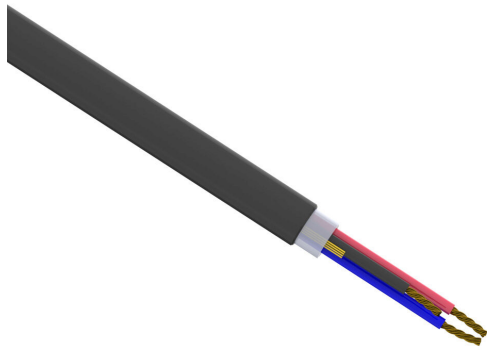

Southwire control cable, unshielded, 3 conductors, 12 AWG, bare copper, PVC/Nylon conductor insulation material, method 1 table 2 color code, PVC jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/VNTC-12-3-BK-1>

Technical Specifications

Brand	Southwire	Shielding	Unshielded
Item	Cable	Jacket Material	PVC
Wire/Cable Type	Control	Jacket Color	Black
UL Wire/Cable Type	TC-ER	Nominal Overall Cable Diameter	0.45in
Application	General purpose	Bulk Length	Cut to length
Flexibility	Semi-flexible	Package Type	1 to 50ft = Coil, 51 to 195ft = 14 x 7in Reel, 196 to 275ft = 14 x 10in Reel, 276 to 420ft = 16 x 10in Reel, 421 to 590ft = 18 x 10in Reel, 591 to 765ft = 18 x 13in Reel, 766 to 1715ft = 24 x 17in Wooden Reel, 1716 to 2745ft = 30 x 17in Wooden Reel, 2746 to MAX = Large Wooden Reel
Voltage Rating	600V		
Conductors	3 conductors		
Conductor Size	12 AWG		
Conductor Stranding	7-stranded		
Conductor Material	Bare copper		
Conductor Insulation Material	PVC/Nylon		
Conductor Insulation Color	Method 1 table 2 color code		

Agency Approvals

UL Listed File #	E75755
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement