


VNTC-14-4-BK-1 Cut Sheet

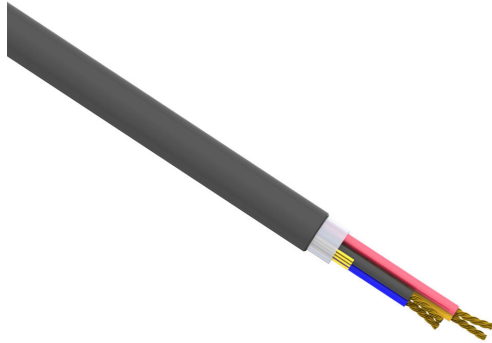

Southwire control cable, unshielded, 4 conductors, 14 AWG, bare copper, PVC/Nylon conductor insulation material, method 1 table 2 color code, PVC jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/VNTC-14-4-BK-1>

Technical Specifications

| | |
|--------------------------------------|-----------------------------|
| Brand | Southwire |
| Item | Cable |
| Wire/Cable Type | Control |
| UL Wire/Cable Type | TC-ER |
| Application | General purpose |
| Flexibility | Semi-flexible |
| Voltage Rating | 600V |
| Conductors | 4 conductors |
| Conductor Size | 14 AWG |
| Conductor Stranding | 7-stranded |
| Conductor Material | Bare copper |
| Conductor Insulation Material | PVC/Nylon |
| Conductor Insulation Color | Method 1 table 2 color code |

| | |
|---------------------------------------|---|
| Shielding | Unshielded |
| Jacket Material | PVC |
| Jacket Color | Black |
| Nominal Overall Cable Diameter | 0.437in |
| Bulk Length | Cut to length |
| Package Type | 1 to 50ft = Coil, 51 to 205ft = 14 x 7in Reel, 206 to 290ft = 14 x 10in Reel, 291 to 445ft = 16 x 10in Reel, 446 to 625ft = 18 x 10in Reel, 626 to 815ft = 18 x 13in Reel, 816 to 1820ft = 24 x 17in Wooden Reel, 1821 to 2910ft = 30 x 17in Wooden Reel, 2911 to MAX = Large Wooden Reel |

Agency Approvals

| | |
|-----------------------------|---|
| UL Listed File # | E75755 |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | None |
| CSA File # | None |
| RoHS Status | Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below) |
| EU REACH | View EU REACH document |
| Other | RoHS Statement |