


VNTC-16-3-BK-1 Cut Sheet

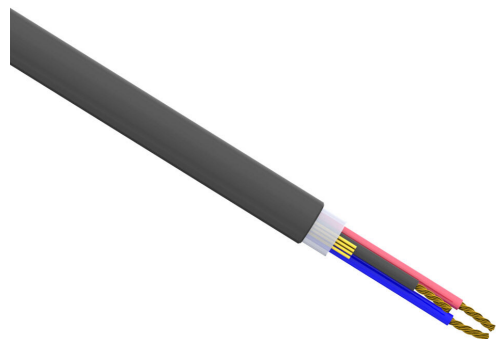

Southwire control cable, unshielded, 3 conductors, 16 AWG, bare copper, PVC/Nylon conductor insulation material, method 1 table 2 color code, PVC jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/VNTC-16-3-BK-1>

Technical Specifications

Brand	Southwire
Item	Cable
Wire/Cable Type	Control
UL Wire/Cable Type	TC-ER
Application	General purpose
Flexibility	Semi-flexible
Voltage Rating	600V
Conductors	3 conductors
Conductor Size	16 AWG
Conductor Stranding	7-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC/Nylon
Conductor Insulation Color	Method 1 table 2 color code

Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Black
Nominal Overall Cable Diameter	0.368in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 25 to 75ft = Coil• 76 to 290ft = 14 x 7in Reel• 291 to 410ft = 14 x 10in Reel• 411 to 630ft = 16 x 10in Reel• 631 to 880ft = 18 x 10in Reel• 881 to 1145ft = 18 x 13in Reel• 1146 to 2565ft = 24 x 17in Wooden Reel• 2566 to 4105ft = 30 x 17in Wooden Reel• 4106 to 5000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E75755
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement