


VNTC-18-10-BK-1 Cut Sheet

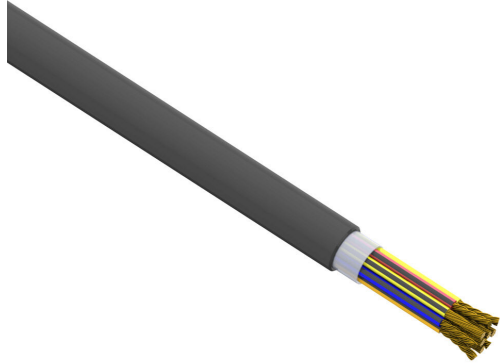

Southwire control cable, unshielded, 10 conductors, 18 AWG, bare copper, PVC/Nylon conductor insulation material, method 1 table 2 color code, PVC jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/VNTC-18-10-BK-1>

Technical Specifications

| | | | |
|--------------------------------------|-----------------------------|---------------------------------------|---|
| Brand | Southwire | Shielding | Unshielded |
| Item | Cable | Jacket Material | PVC |
| Wire/Cable Type | Control | Jacket Color | Black |
| UL Wire/Cable Type | TC-ER | Nominal Overall Cable Diameter | 0.551in |
| Application | General purpose | Bulk Length | Cut to length |
| Flexibility | Semi-flexible | Package Type | <ul style="list-style-type: none">• 25 to 50ft = Coil• 51 to 130ft = 14 x 7in Reel• 131 to 185ft = 14 x 10in Reel• 186 to 280ft = 16 x 10in Reel• 281 to 395ft = 18 x 10in Reel• 396 to 510ft = 18 x 13in Reel• 511 to 1145ft = 24 x 17in Wooden Reel• 1146 to 1830ft = 30 x 17in Wooden Reel• 1831 to 5000ft = Large Wooden Reel |
| Voltage Rating | 600V | | |
| Conductors | 10 conductors | | |
| Conductor Size | 18 AWG | | |
| Conductor Stranding | 7-stranded | | |
| Conductor Material | Bare copper | | |
| Conductor Insulation Material | PVC/Nylon | | |
| Conductor Insulation Color | Method 1 table 2 color code | | |

Agency Approvals

| | |
|-----------------------------|---|
| UL Listed File # | E75755 |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | None |
| CSA File # | None |
| RoHS Status | Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below) |
| EU REACH | View EU REACH document |
| Other | RoHS Statement |