


# VNTC-18-24-BK-1 Cut Sheet

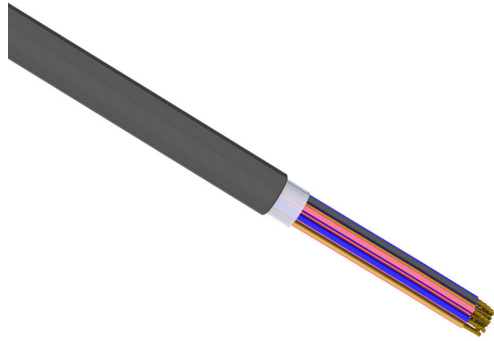

Southwire control cable, unshielded, 24 conductors, 18 AWG, bare copper, PVC/Nylon conductor insulation material, method 1 table 2 color code, PVC jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/VNTC-18-24-BK-1>

## Technical Specifications

<b>Brand</b>	Southwire	<b>Shielding</b>	Unshielded
<b>Item</b>	Cable	<b>Jacket Material</b>	PVC
<b>Wire/Cable Type</b>	Control	<b>Jacket Color</b>	Black
<b>UL Wire/Cable Type</b>	TC-ER	<b>Nominal Overall Cable Diameter</b>	0.826in
<b>Application</b>	General purpose	<b>Bulk Length</b>	Cut to length
<b>Flexibility</b>	Semi-flexible	<b>Package Type</b>	1 to 40ft = Coil, 41 to 50ft = 14 x 7in Reel, 51 to 75ft = 14 x 10in Reel, 76 to 120ft = 16 x 10in Reel, 121 to 170ft = 18 x 10in Reel, 171 to 220ft = 18 x 13in Reel, 221 to 480ft = 24 x 17in Wooden Reel, 481 to 795ft = 30 x 17in Wooden Reel, 796 to MAX = Large Wooden Reel
<b>Voltage Rating</b>	600V		
<b>Conductors</b>	24 conductors		
<b>Conductor Size</b>	18 AWG		
<b>Conductor Stranding</b>	7-stranded		
<b>Conductor Material</b>	Bare copper		
<b>Conductor Insulation Material</b>	PVC/Nylon		
<b>Conductor Insulation Color</b>	Method 1 table 2 color code		

## Agency Approvals

<b>UL Listed File #</b>	E75755
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	None
<b>CSA File #</b>	None
<b>RoHS Status</b>	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>
<b>Other</b>	<a href="#">RoHS Statement</a>